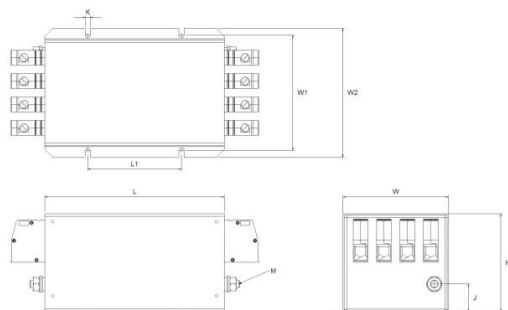


EMI Filters, Three Phase, FLLD4-TH, 530 VAC, 8 A, 120x115x80mm

**Dimensions**

<b>L</b>	120mm NOM
<b>W</b>	115mm NOM
<b>H</b>	80mm NOM
<b>L1</b>	80mm NOM
<b>W1</b>	127.5mm NOM
<b>W2</b>	143mm NOM
<b>J</b>	32mm NOM
<b>K</b>	6.5mm NOM
<b>M (Earth)</b>	Threaded Studs M6

**Packaging Specifications**

<b>Packaging:</b>	Bulk
<b>Packaging Quantity:</b>	1
<b>Weight:</b>	800 g

**General Information**

<b>Style:</b>	Chassis Mount
<b>Series:</b>	FLLD4-TH
<b>Description:</b>	EMI Filter, Chassis Mount, Compact
<b>Features:</b>	High Performance
<b>RoHS:</b>	Yes

**Specifications**

<b>Voltage AC:</b>	530/305 VAC
<b>Rated Frequency:</b>	50-60 Hz
<b>Current:</b>	8 A (50C)
<b>Rated Temperature:</b>	50C
<b>Temperature Range:</b>	-25/+100C
<b>Climate Category:</b>	25/100/21
<b>Test Voltage DC (P to P):</b>	2250 VDC
<b>Test Voltage DC (P to E):</b>	3000 VDC
<b>Power Loss:</b>	3 W (25C 50 Hz)
<b>Leakage Current:</b>	11 mA