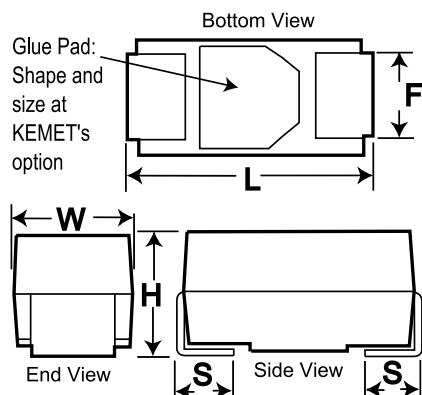


Polymer Aluminum, 125C, A700, 100 uF, 20%, 6.3 V, -55/+125C

**Dimensions**

L	7.3mm +/-0.3mm
W	4.3mm +/-0.3mm
H	2.8mm +/-0.3mm
S	1.3mm +/-0.3mm
F	2.4mm +/-0.1mm

Packaging Specifications

Weight:	196.58 mg
Packaging:	T&R, 180mm
Packaging Quantity:	500

General Information

Dielectric:	Polymer Aluminum
Style:	SMD Chip
Series:	A700
Footprint:	7343
Description:	Surface Mount, Polymer Aluminum
RoHS:	Yes
Termination:	Tin
Notes:	D/7343-31

Specifications

Capacitance:	100 uF
Capacitance Tolerance:	20%
Voltage DC:	6.3 VDC
Temperature Range:	-55/+125C
Rated Temperature:	125C
Dissipation Factor:	6%
Resistance:	15 mOhms (100kHz)
Current:	4100 mAmps (100kHz)
Leakage Current:	25.2 uAmps (5min 20C)