


Film, Metallized Polypropylene, Power, C4AT, 6.8 uF, 5%, 450 V, 70C, Lead Spacing = 27.5mm

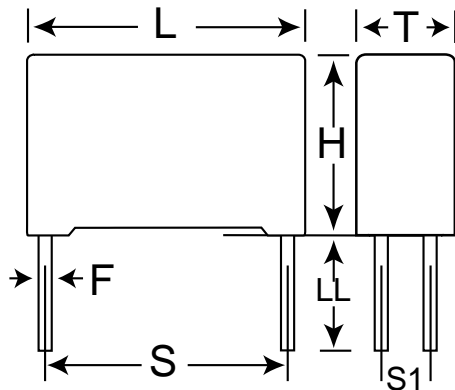

Dimensions

L	32mm NOM
H	37mm NOM
T	22mm NOM
S	27.5mm +/-0.4mm
S1	10.2mm +/-0.4mm
LL	6mm -2mm

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	64

General Information

Dielectric:	Metallized Polypropylene
Style:	Radial
Series:	C4AT
Features:	Switching
RoHS:	Yes
Lead:	4 Wire Leads

Specifications

Capacitance:	6.8 uF
Capacitance Tolerance:	5%
Voltage DC:	450 VDC
Voltage AC:	275 VAC
Temperature Range:	-40/+85C
Rated Temperature:	70C
Dissipation Factor:	0.05%
Max dVdt:	82 V
Resistance:	1.6 mOhms (100kHz)
Current:	29 Amps (100kHz 70C), 554 Amps (Peak)