


KEMET Part Number: EFF(007)-240X240T0800
(UFSEFF007AT080, EFF(007)240x240T0800)

Flex Suppressors, Commercial Grade, EFF

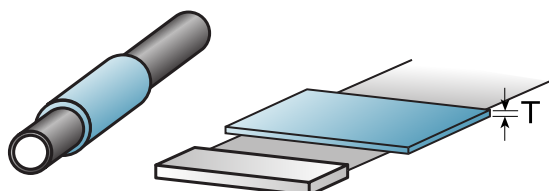

General Information

Style:	Sheet
Brand:	TOKIN
Series:	EFF
Description:	Flex Suppressor Halogen Free Type
Features:	Extra High Magnetic Permeability
RoHS:	Yes
Approvals:	UL94 V-0, UL File No. E176124
Environment:	Halogen Free, PVC Free, Lead Free

Dimensions

Sheet Size	240x240mm
T	0.07mm +/-0.03mm

Packaging Specifications

Tape Description:	Without PET Tape (Txx00)
Tape Thickness:	.03mm

Specifications

Temperature Range:	-40/+105C
Magnetic Permeability:	130 TYP At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	0.1 MOhms MIN
Specific Gravity:	3.6 Atm TYP
Conductivity:	0.4 W/m K
Tensile Strength:	6.9 MPa MIN