


Aluminum Electrolytic, 105C, ELG, 330 uF, 20%, 400 V, -25/+105C

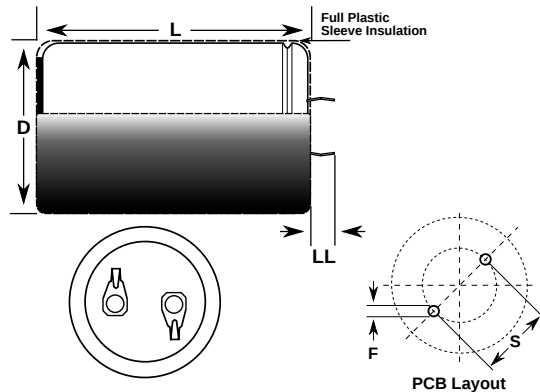

**Dimensions**

|    |               |
|----|---------------|
| D  | 35mm +/-1mm   |
| L  | 35mm +/-2mm   |
| S  | 10mm +/-0.5mm |
| LL | 5.8mm +/-1mm  |
| F  | 2mm +/-0.1mm  |

**Packaging Specifications**

|            |      |
|------------|------|
| Packaging: | Bulk |
|------------|------|

**General Information**

|              |                                |
|--------------|--------------------------------|
| Dielectric:  | Aluminum Electrolytic          |
| Series:      | ELG                            |
| Description: | Snap-In, Aluminum Electrolytic |
| RoHS:        | Yes                            |
| Lead:        | 2 Pin                          |

**Specifications**

|                        |                          |
|------------------------|--------------------------|
| Capacitance:           | 330 uF                   |
| Capacitance Tolerance: | 20%                      |
| Voltage DC:            | 400 VDC, 450 VDC (Surge) |
| Temperature Range:     | -25/+105C                |
| Rated Temperature:     | 105C                     |
| Life:                  | 2000 Hrs                 |
| Dissipation Factor:    | 15% 120Hz 20C            |
| Resistance:            | 195 mOhms (20kHz)        |
| Current:               | 1350 mAmps (120Hz)       |
| Leakage Current:       | 2600 uAmps (5min 20C)    |