


**KEMET Part Number: 080MS26AAMK1STD**  
(A902GF080K260A)

Aluminum Electrolytic, Motor Start, MS/A902, 80 uF, 10%, 260 V, -20/+60C

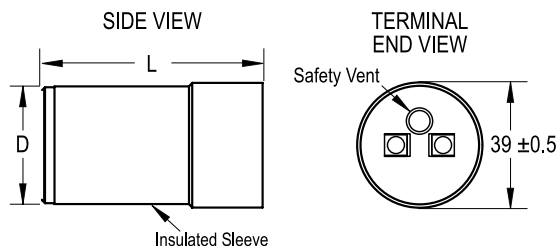

Dimensions	
D	38mm +/-0.5mm
L	75mm MAX

Packaging Specifications	
Packaging:	Bulk

General Information	
Dielectric:	Aluminum Electrolytic
Series:	MS/A902
Description:	Motor Start Aluminum Electrolytic
RoHS:	Yes
Lead:	Quick Connect

Specifications	
Capacitance:	80 uF
Capacitance Tolerance:	10%
Voltage AC:	260 VAC
Temperature Range:	-20/+60C
Rated Temperature:	60C
Life:	500 Hrs