


**KEMET Part Number: 200MS22ACMA1STD**  
(A902GP200V220A)

Aluminum Electrolytic, Motor Start, MS/A902, 200 uF, -0/+25%, 220 V, -20/+60C

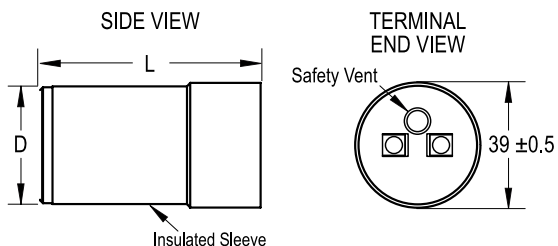

Dimensions	
D	38mm +/-0.5mm
L	116mm MAX

Packaging Specifications	
Packaging:	Bulk

General Information	
Dielectric:	Aluminum Electrolytic
Series:	MS/A902
Description:	Motor Start Aluminum Electrolytic
RoHS:	Yes
Lead:	Quick Connect

Specifications	
Capacitance:	200 uF
Capacitance Tolerance:	-0/+25%
Voltage AC:	220 VAC
Temperature Range:	-20/+60C
Rated Temperature:	60C
Life:	500 Hrs