


KEMET Part Number: 200MS26ACMK1STD
(A902GP200K260A)

Aluminum Electrolytic, Motor Start, MS/A902, 200 uF, 10%, 260 V, -20/+60C

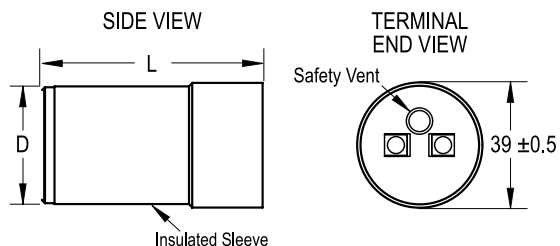

| Dimensions | |
|------------|---------------|
| D | 38mm +/-0.5mm |
| L | 116mm MAX |

| Packaging Specifications | |
|--------------------------|------|
| Packaging: | Bulk |

| General Information | |
|---------------------|-----------------------------------|
| Dielectric: | Aluminum Electrolytic |
| Series: | MS/A902 |
| Description: | Motor Start Aluminum Electrolytic |
| RoHS: | Yes |
| Lead: | Quick Connect |

| Specifications | |
|------------------------|----------|
| Capacitance: | 200 uF |
| Capacitance Tolerance: | 10% |
| Voltage AC: | 260 VAC |
| Temperature Range: | -20/+60C |
| Rated Temperature: | 60C |
| Life: | 500 Hrs |