


Film, Metallized Paper, Resistor/Capacitor, P410, 0.068 uF, 20%, 1,000 V, 85C, Lead Spacing = 20.3mm

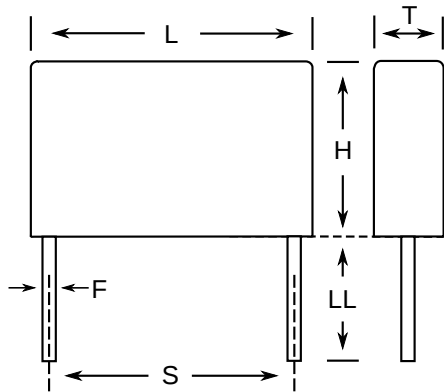

General Information	
Dielectric:	Metallized Paper
Style:	Radial
Series:	P410
Features:	Pulse
RoHS:	Yes
Lead:	Wire Leads
Approvals:	ENEC, UL, cUL
Construction:	Molded
Miscellaneous:	Resistor Tolerance: +/-30%. Resistor= 100 Ohms

Dimensions	
L	24mm MAX
H	16.5mm MAX
T	11.3mm MAX
S	20.3mm +/-0.4mm
LL	30mm +5mm
F	0.8mm +/-0.05mm

Specifications	
Capacitance:	0.068 uF
Capacitance Tolerance:	20%
Voltage DC:	1000 VDC
Voltage AC:	300 VAC
Temperature Range:	-40/+85C
Rated Temperature:	85C
Insulation Resistance:	3 GOhms
Safety Class:	X1

Packaging Specifications	
Packaging:	Bulk
Packaging Quantity:	150