


Film, Metallized Paper, Resistor/Capacitor, P410, 0.1 uF, 20%, 1,000 V, 85C, Lead Spacing = 25.4mm

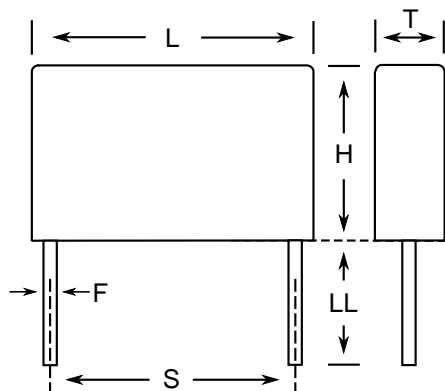

General Information

| | |
|-----------------------|---|
| Dielectric: | Metallized Paper |
| Style: | Radial |
| Series: | P410 |
| Features: | Pulse |
| RoHS: | Yes |
| Lead: | Wire Leads |
| Approvals: | ENEC, UL, cUL |
| Construction: | Molded |
| Miscellaneous: | Resistor Tolerance: +/-30%. Resistor= 100 Ohms |

Dimensions

| | |
|-----------|-----------------|
| L | 30.5mm MAX |
| H | 16.1mm MAX |
| T | 10.6mm MAX |
| S | 25.4mm +/-0.4mm |
| LL | 30mm +5mm |
| F | 1mm +/-0.05mm |

Specifications

| | |
|-------------------------------|----------|
| Capacitance: | 0.1 uF |
| Capacitance Tolerance: | 20% |
| Voltage DC: | 1000 VDC |
| Voltage AC: | 300 VAC |
| Temperature Range: | -40/+85C |
| Rated Temperature: | 85C |
| Insulation Resistance: | 3 GOhms |
| Safety Class: | X1 |

Packaging Specifications

| | |
|----------------------------|------|
| Packaging: | Bulk |
| Packaging Quantity: | 150 |