


Film, Metallized Polyester Stacked, Commercial Grade, R60, 1.5 uF, 5%, 63 V, 85C, Lead Spacing = 10mm

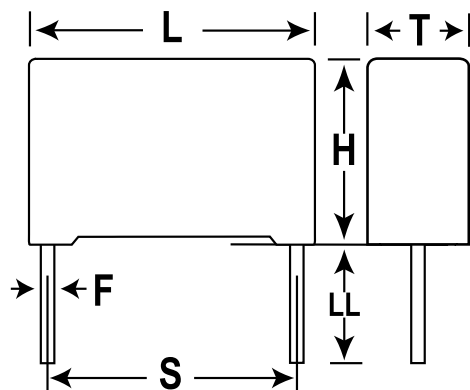

#### Dimensions

L	13mm +0.2mm
H	11mm +1mm
T	5mm +0.2mm
S	10mm +/-0.4mm
LL	25mm +2/-1mm
F	0.6mm +/-0.05mm

#### Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	1500

#### General Information

Dielectric:	Metallized Polyester Stacked
Style:	Radial
Series:	R60
Features:	Pulse
RoHS:	Yes
Lead:	Wire Leads
Approvals:	AEC-Q200
AEC-Q200:	Yes
Miscellaneous:	Upper Operating Temperature Of 125C Is Allowed For A Maximum Operating Time Of 1,000 Hours. Above 85C, DC And AC Voltage Derating Is 1.25%/C.

#### Specifications

Capacitance:	1.5 uF
Capacitance Tolerance:	5%
Voltage DC:	63 VDC
Voltage AC:	40 VAC
Temperature Range:	-55/+105C
Rated Temperature:	85C
Dissipation Factor:	1% 1kHz
Insulation Resistance:	833.3 MOhms
Max dVdt:	50 V
Inductance:	9 nH