


KEMET Part Number: SC-01-10GS
(UALSC0110GS000)

Choke, SC-G/GS, 1000 uH

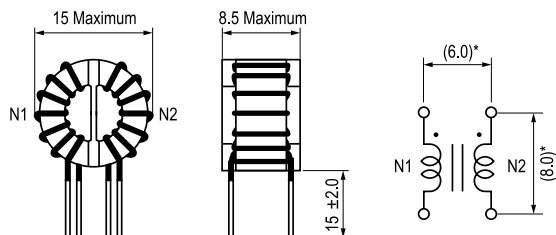

Dimensions

L	15mm MAX
T	8.5mm MAX
H	15mm MAX
S	8mm MAX
S1	6mm NOM
LL	15mm +/-2mm
Wire Size	0.3mm

Packaging Specifications

Weight:	2 g
----------------	-----

General Information

Style:	Through-Hole Toroid
Series:	SC-G/GS
Description:	Miniature Common Mode Filter
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 100kHz 1mA KC547 (*=1mA KC547)
Notes:	Lead Spacing (S/S1) Are For Reference Only.

Specifications

Inductance:	1000 uH
Rated Temperature:	120C
Current:	1 Amps
Voltage AC:	250 VAC
DC Resistance:	130 mOhms
Insulation Resistance:	100 MOhms