


KEMET Part Number: SC-03-10GJ
(UALSC0310GJ000)

Choke, SC-GJ, 1000 uH

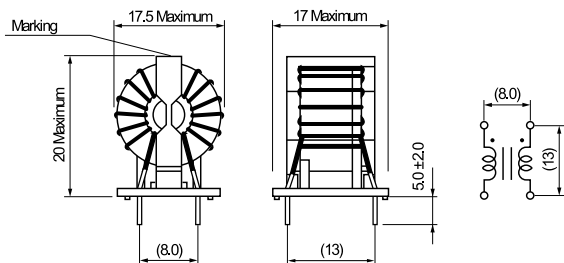

Dimensions

Dimensions	
L	17.5mm MAX
T	17mm MAX
H	20mm MAX
S	13mm MAX
S1	8mm NOM
LL	5mm +/-2mm
Wire Size	0.6mm

Packaging Specifications

Weight:	9 g
---------	-----

General Information

Style:	Through-Hole Toroid
Series:	SC-GJ
Description:	Common Mode Filter With Base Plate
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 100kHz 1mA KC547
Notes:	Lead Spacing (S/S1) Are For Reference Only.

Specifications

Inductance:	1000 uH
Rated Temperature:	120C
Current:	3 Amps
Voltage AC:	250 VAC
DC Resistance:	40 mOhms
Insulation Resistance:	100 MOhms