


**KEMET Part Number: SC-10-20J**  
(UALSC1020J0000)

Choke, SC-J, 2000 uH

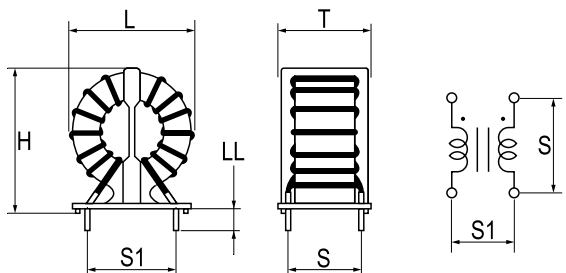

#### Dimensions

<b>L</b>	42mm MAX
<b>T</b>	29mm MAX
<b>H</b>	44mm MAX
<b>S</b>	22mm MAX
<b>S1</b>	18mm NOM
<b>LL</b>	5mm +/-2mm
<b>Wire Size</b>	1.4mm

#### Packaging Specifications

<b>Weight:</b>	70 g
----------------	------

#### General Information

<b>Style:</b>	Through-Hole Toroid
<b>Series:</b>	SC-J
<b>Description:</b>	Common Mode Filter With Base Plate
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	Inductance Measurement Condition: 100kHz 1mA KC547
<b>Notes:</b>	Lead Spacing (S/S1) Are For Reference Only.

#### Specifications

<b>Inductance:</b>	2000 uH
<b>Rated Temperature:</b>	120C
<b>Current:</b>	10 Amps
<b>Voltage AC:</b>	250 VAC
<b>DC Resistance:</b>	22 mOhms
<b>Insulation Resistance:</b>	100 MOhms