


KEMET Part Number: SC-02-300JV
(UALSC02300JV00)

Choke, SC-JV, 0.044 H

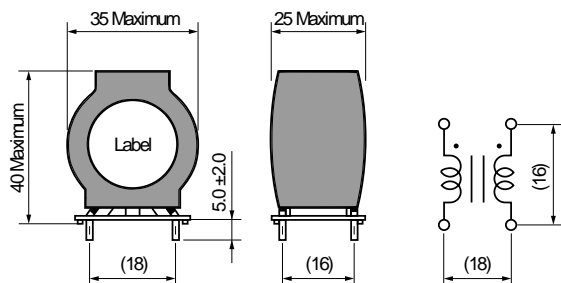

Dimensions

L	35mm MAX
T	25mm MAX
H	40mm MAX
S	16mm MAX
S1	18mm NOM
LL	5mm +/-2mm
Wire Size	0.6mm

Packaging Specifications

Weight:	45 g
----------------	------

General Information

Style:	Through-Hole Toroid
Series:	SC-JV
Description:	Common Mode Filter With Base Plate And Shrink Wrapped Body
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 16kHz 0.2mA KC547
Notes:	Lead Spacing (S/S1) Are For Reference Only.

Specifications

Inductance:	44000 uH
Rated Temperature:	105C
Current:	2 Amps
Voltage AC:	250 VAC
DC Resistance:	300 mOhms
Insulation Resistance:	50 MOhms