


**KEMET Part Number: SC-04-200JV**  
(UALSC04200JV00)

Choke, SC-JV, 0.029 H

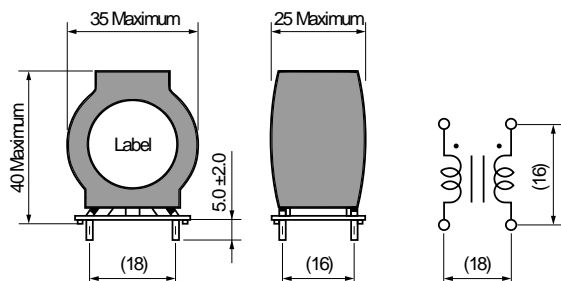

#### Dimensions

<b>L</b>	35mm MAX
<b>T</b>	25mm MAX
<b>H</b>	40mm MAX
<b>S</b>	16mm MAX
<b>S1</b>	18mm NOM
<b>LL</b>	5mm +/-2mm
<b>Wire Size</b>	0.8mm

#### Packaging Specifications

<b>Weight:</b>	45 g
----------------	------

#### General Information

<b>Style:</b>	Through-Hole Toroid
<b>Series:</b>	SC-JV
<b>Description:</b>	Common Mode Filter With Base Plate And Shrink Wrapped Body
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	Inductance Measurement Condition: 16kHz 0.2mA KC547
<b>Notes:</b>	Lead Spacing (S/S1) Are For Reference Only.

#### Specifications

<b>Inductance:</b>	29000 uH
<b>Rated Temperature:</b>	105C
<b>Current:</b>	4 Amps
<b>Voltage AC:</b>	250 VAC
<b>DC Resistance:</b>	150 mOhms
<b>Insulation Resistance:</b>	50 MOhms