



KEMET Part Number: SMR5473J50J01L16.5CBULK
(F211JF473J050ALG5C)

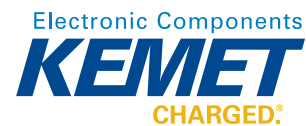

Film, Metallized PPS, Commercial Grade, SMR/F211, 0.047 uF, 5%, 50 V, 125C, Lead Spacing = 5mm

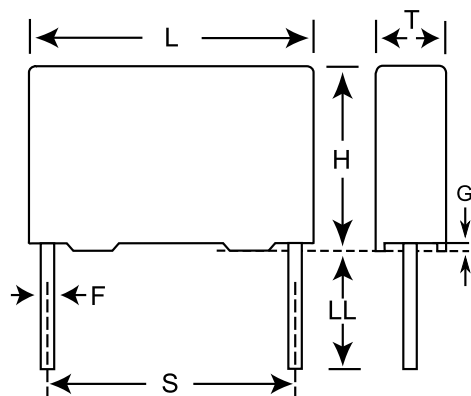

Dimensions

L	7.2mm MAX
H	6.5mm MAX
T	2.5mm MAX
S	5mm +/-0.4mm
LL	16.5mm +0.5mm
F	0.5mm +/-0.05mm
G	0.5mm NOM

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	2000

General Information

Dielectric:	Metallized PPS
Style:	Radial
Series:	SMR/F211
RoHS:	Yes
Lead:	Wire Leads
Miscellaneous:	The rated voltage decreases 2%/C between +125C and +150C
Notes:	Case Size = JF

Specifications

Capacitance:	0.047 uF
Capacitance Tolerance:	5%
Voltage DC:	50 VDC
Voltage AC:	30 VAC
Temperature Range:	-55/+150C
Rated Temperature:	125C
Dissipation Factor:	0.15% 1kHz, 0.25% 10kHz, 0.6% 100kHz
Insulation Resistance:	15 GOhms
Max dVdt:	6 V

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.



© 2006 - 2017 IntelliData.net