


KEMET Part Number: SS11VL-R08125
(UAL11VLR081250)

Commercial Grade, SS11VL, 0.0125 H

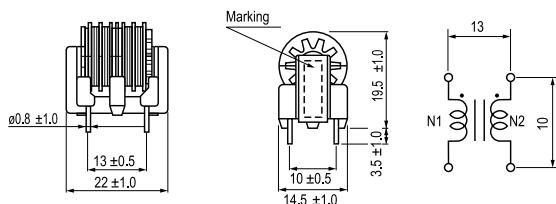

General Information

Style:	Through-Hole Choke
Series:	SS11VL
Description:	Common Mode Filter, Height: 20.5mm MAX
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 1kHz 1V KC530
Notes:	Lead Spacing (S/S1) Are For Reference Only.

Dimensions

L	22mm +/-1mm
T	14.5mm +/-1mm
H	19.5mm +/-1mm
S	10mm MAX
S1	13mm NOM
LL	3.5mm +/-1mm
F	0.8mm NOM

Specifications

Inductance:	12500 uH
Rated Temperature:	120C
Current:	0.8 Amps
Voltage AC:	250 VAC
DC Resistance:	740 mOhms
Insulation Resistance:	100 MOhms

Packaging Specifications

Weight:	9.8 g
----------------	-------