


KEMET Part Number: SS20H-10080
(UAL20H10080000)

Commercial Grade, SS20H, 8000 uH

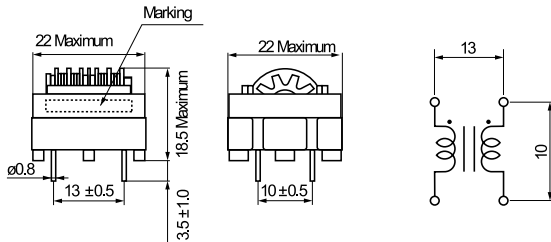

Dimensions

Dimension	Value
L	22mm MAX
T	22mm MAX
H	18.5mm MAX
S	10mm MAX
S1	13mm NOM
LL	3.5mm +/-1mm
F	0.8mm +/-0.1mm

Packaging Specifications

Weight:	12 g
----------------	------

General Information

Style:	Through-Hole Choke
Series:	SS20H
Description:	Common Mode Filter
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 1kHz 1V KC530
Notes:	Lead Spacing (S/S1) Are For Reference Only.

Specifications

Inductance:	8000 uH
Rated Temperature:	120C
Current:	1 Amps
Voltage AC:	250 VAC
DC Resistance:	420 mOhms
Insulation Resistance:	100 MOhms