 



KEMET Part Number: SS24V-R08250-CH
(UAL24VR08250CH, SS24V/H-R08250-CH)

Commercial Grade, SS24V/H-CH, 0.025 H

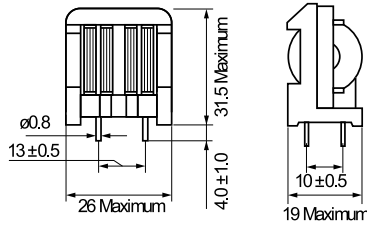

Dimensions

Dimension	Value
L	26mm MAX
T	19mm MAX
H	31.5mm MAX
S	10mm +/-0.5mm
S1	13mm +/-0.5mm
LL	4mm +/-1mm
F	0.8mm NOM

Packaging Specifications

Weight:	18.8 g
----------------	--------

General Information

Style:	Through-Hole Choke
Series:	SS24V/H-CH
Description:	Common Mode Filter
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 1kHz 1V KC530

Specifications

Inductance:	25000 uH
Rated Temperature:	120C
Current:	0.8 Amps
Voltage AC:	250 VAC
DC Resistance:	750 mOhms
Insulation Resistance:	100 MOhms