
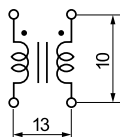


**KEMET Part Number: SS24V-R15080-CH**  
(UAL24VR15080CH, SS24V/H-R15080-CH)

Commercial Grade, SS24V/H-CH, 8000 uH

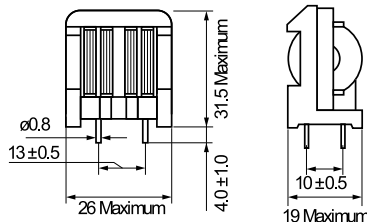

**Dimensions**

| Dimension | Value         |
|-----------|---------------|
| L         | 26mm MAX      |
| T         | 19mm MAX      |
| H         | 31.5mm MAX    |
| S         | 10mm +/-0.5mm |
| S1        | 13mm +/-0.5mm |
| LL        | 4mm +/-1mm    |
| F         | 0.8mm NOM     |

**Packaging Specifications**

|                |      |
|----------------|------|
| <b>Weight:</b> | 19 g |
|----------------|------|

**General Information**

|                       |   |
|-----------------------|---|
| <b>Style:</b>         | Through-Hole Choke                              |
| <b>Series:</b>        | SS24V/H-CH                                      |
| <b>Description:</b>   | Common Mode Filter                              |
| <b>RoHS:</b>          | Yes   |
| <b>Miscellaneous:</b> | Inductance Measurement Condition: 1kHz 1V KC530 |

**Specifications**

|                               |           |
|-------------------------------|-----------|
| <b>Inductance:</b>            | 8000 uH   |
| <b>Rated Temperature:</b>     | 120C      |
| <b>Current:</b>               | 1.5 Amps  |
| <b>Voltage AC:</b>            | 250 VAC   |
| <b>DC Resistance:</b>         | 240 mOhms |
| <b>Insulation Resistance:</b> | 100 MOhms |