


**KEMET Part Number: SS26V-R200102**  
(UAL26VR2001020)

Commercial Grade, SS26V, 0.0102 H

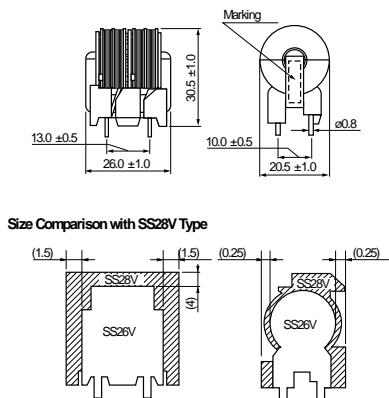

General Information	
<b>Style:</b>	Through-Hole Choke
<b>Series:</b>	SS26V
<b>Description:</b>	Common Mode Filter
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	Inductance Measurement Condition: 1kHz 1V KC530
<b>Notes:</b>	Replacement For SS28V Type And SS24V Type. Replacement For SS28V Type And SS24V Type

Dimensions	
<b>L</b>	26mm +/-1mm
<b>T</b>	20.5mm +/-1mm
<b>H</b>	30.5mm +/-1mm
<b>S</b>	10mm +/-0.5mm
<b>S1</b>	13mm +/-0.5mm
<b>F</b>	0.8mm NOM

Specifications	
<b>Inductance:</b>	10200 uH
<b>Rated Temperature:</b>	120C
<b>Current:</b>	2 Amps
<b>Voltage AC:</b>	250 VAC
<b>DC Resistance:</b>	250 mOhms
<b>Insulation Resistance:</b>	100 MOhms

Packaging Specifications	
<b>Weight:</b>	25.9 g