


KEMET Part Number: SS26V-R250061
(UAL26VR2500610)

Commercial Grade, SS26V, 6100 uH

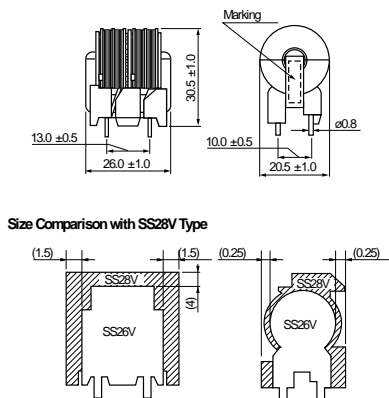

General Information	
Style:	Through-Hole Choke
Series:	SS26V
Description:	Common Mode Filter
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 1kHz 1V KC530
Notes:	Replacement For SS28V Type And SS24V Type. Replacement For SS28V Type And SS24V Type

Dimensions	
L	26mm +/-1mm
T	20.5mm +/-1mm
H	30.5mm +/-1mm
S	10mm +/-0.5mm
S1	13mm +/-0.5mm
F	0.8mm NOM

Specifications	
Inductance:	6100 uH
Rated Temperature:	120C
Current:	2.5 Amps
Voltage AC:	250 VAC
DC Resistance:	150 mOhms
Insulation Resistance:	100 MOhms

Packaging Specifications	
Weight:	24.3 g