



KEMET Part Number: SS30V-R180190
(UAL30VR1801900)

Commercial Grade, SS30V, 0.019 H

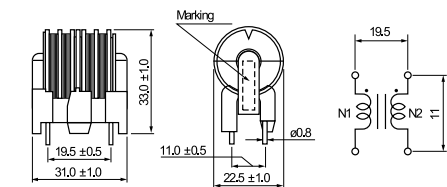

Size Comparison with SS35V Type

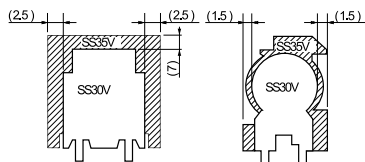

General Information

Style:	Through-Hole Choke
Series:	SS30V
Description:	Common Mode Filter (Class B)
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 1kHz 1V KC530
Notes:	Replacement For SS35V Type And SS28V Type. Replacement For SS35V Type And SS28V Type

Dimensions

L	31mm +/-1mm
T	22.5mm +/-1mm
H	33mm +/-1mm
S	11mm +/-0.5mm
S1	19.5mm +/-0.5mm
F	0.8mm NOM

Specifications

Inductance:	19000 uH
Rated Temperature:	120C
Current:	1.8 Amps
Voltage AC:	250 VAC
DC Resistance:	230 mOhms
Insulation Resistance:	100 MOhms

Packaging Specifications

Weight:	35.2 g
----------------	--------