


**KEMET Part Number: SU10VFC-R15019**  
(UALSU10VR15019)

Commercial Grade, SU-10VFC-R, 1900 uH

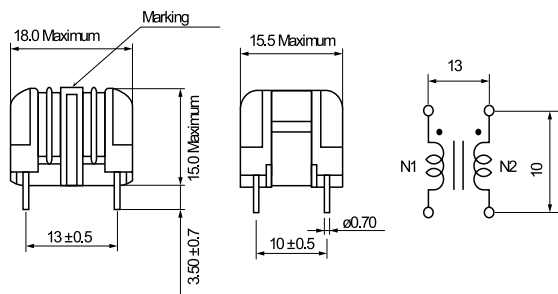

**Dimensions**

Dimension	Value
L	18mm MAX
T	15.5mm MAX
H	15mm MAX
S	10mm +/-0.5mm
S1	13mm +/-0.5mm
LL	3.5mm +/-0.7mm
F	0.7mm NOM

**Packaging Specifications**

<b>Weight:</b>	6.5 g
----------------	-------

**General Information**

<b>Style:</b>	Through-Hole Choke
<b>Series:</b>	SU-10VFC-R
<b>Description:</b>	Common Mode Filter, Height: 15mm MAX
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	Inductance Measurement Condition: 1kHz 1V KC530

**Specifications**

<b>Inductance:</b>	1900 uH
<b>Rated Temperature:</b>	120C
<b>Current:</b>	1.5 Amps
<b>Voltage AC:</b>	250 VAC
<b>DC Resistance:</b>	240 mOhms
<b>Insulation Resistance:</b>	100 MOhms