


**KEMET Part Number: SU16VD-40010**  
(UALSU16VD40010)

Commercial Grade, SU-16VD, 10 uH

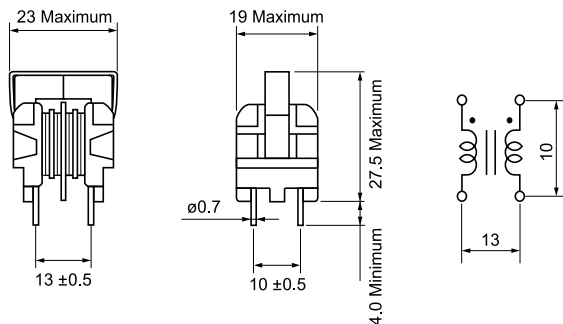

**Dimensions**

<b>L</b>	23mm MAX
<b>T</b>	19mm MAX
<b>H</b>	27.5mm MAX
<b>S</b>	10mm +/-0.5mm
<b>S1</b>	13mm +/-0.5mm
<b>LL</b>	4mm MIN
<b>F</b>	0.7mm NOM

**Packaging Specifications**

<b>Weight:</b>	11.6 g
----------------	--------

**General Information**

<b>Style:</b>	Through-Hole Choke
<b>Series:</b>	SU-16VD
<b>Description:</b>	High Frequency Common Mode Filter
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	Inductance Measurement Condition: 1kHz 1V KC530

**Specifications**

<b>Inductance:</b>	10 uH
<b>Rated Temperature:</b>	120C
<b>Current:</b>	4 Amps
<b>Voltage AC:</b>	250 VAC
<b>DC Resistance:</b>	40 mOhms
<b>Insulation Resistance:</b>	100 MOhms