


KEMET Part Number: SU9V-R01180
(UALSU9VR011800, SU9V/H-R01180)

Commercial Grade, SU-9V-R/9H-R, 0.018 H

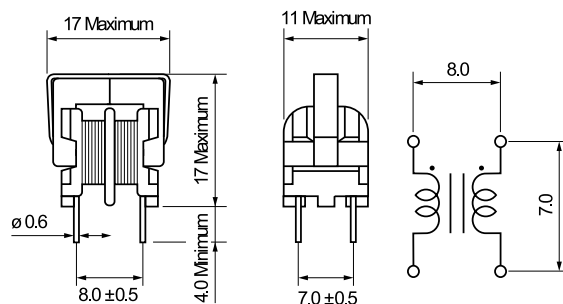

Dimensions

| | |
|----|--------------|
| L | 17mm MAX |
| T | 11mm MAX |
| H | 17mm MAX |
| S | 7mm +/-0.5mm |
| S1 | 8mm +/-0.5mm |
| LL | 4mm MIN |
| F | 0.6mm NOM |

Packaging Specifications

| | |
|---------|-----|
| Weight: | 3 g |
|---------|-----|

General Information

| | |
|----------------|--|
| Style: | Through-Hole Choke |
| Series: | SU-9V-R/9H-R |
| Description: | Common Mode Filter |
| RoHS: | Yes |
| Miscellaneous: | Inductance Measurement Condition: 1kHz 1V KC530 |

Specifications

| | |
|------------------------|-----------|
| Inductance: | 18000 uH |
| Rated Temperature: | 120C |
| Current: | 0.1 Amps |
| Voltage AC: | 250 VAC |
| DC Resistance: | 8 Ohms |
| Insulation Resistance: | 100 MOhms |