


**KEMET Part Number: SU9V-R05034**  
(UALSU9VR050340, SU9V/H-R05034)

Commercial Grade, SU-9V-R/9H-R, 3400 uH

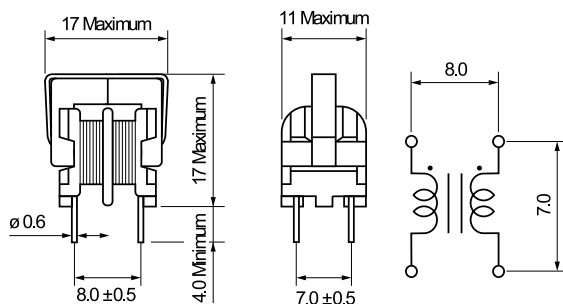

**Dimensions**

<b>L</b>	17mm MAX
<b>T</b>	11mm MAX
<b>H</b>	17mm MAX
<b>S</b>	7mm +/-0.5mm
<b>S1</b>	8mm +/-0.5mm
<b>LL</b>	4mm MIN
<b>F</b>	0.6mm NOM

**Packaging Specifications**

<b>Weight:</b>	3.5 g
----------------	-------

**General Information**

<b>Style:</b>	Through-Hole Choke
<b>Series:</b>	SU-9V-R/9H-R
<b>Description:</b>	Common Mode Filter
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	Inductance Measurement Condition: 1kHz 1V KC530

**Specifications**

<b>Inductance:</b>	3400 uH
<b>Rated Temperature:</b>	120C
<b>Current:</b>	0.5 Amps
<b>Voltage AC:</b>	250 VAC
<b>DC Resistance:</b>	1 Ohms
<b>Insulation Resistance:</b>	100 MOhms