


**KEMET Part Number: SU9VD-07020**  
(UALSU9VD070200)

Commercial Grade, SU-9VD, 20 uH

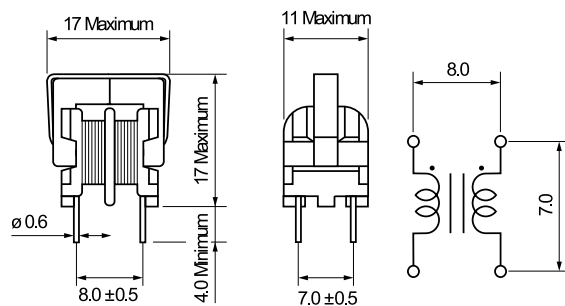

#### Dimensions

Dimension	Value
L	17mm MAX
T	11mm MAX
H	17mm MAX
S	7mm +/-0.5mm
S1	8mm +/-0.5mm
LL	4mm MIN
F	0.6mm NOM

#### Packaging Specifications

<b>Weight:</b>	2.8 g
----------------	-------

#### General Information

<b>Style:</b>	Through-Hole Choke
<b>Series:</b>	SU-9VD
<b>Description:</b>	High Frequency Common Mode Filter
<b>RoHS:</b>	Yes
<b>Miscellaneous:</b>	Inductance Measurement Condition: 1kHz 1V KC530

#### Specifications

<b>Inductance:</b>	20 uH
<b>Rated Temperature:</b>	120C
<b>Current:</b>	0.7 Amps
<b>Voltage AC:</b>	250 VAC
<b>DC Resistance:</b>	120 mOhms
<b>Insulation Resistance:</b>	100 MOhms