


WB3032M - Wire Wrapping Bit, 30-32 AWG - Data Sheet

Fully compatible with any make or model wire wrapping tool. Gauge Size: 30-32 AWG. Wrap Type: Modified. Max Insulation Diameter “: 0.027. Minimum Terminal Diagonal “: 0.034. Max Terminal Diagonal “: 0.038. Terminal Hole Depth “: 0.75. Effective Radius “: 0.064. Terminal Hole Diameter “: 0.04. This tool is recommended for .025” square terminals on .100” center to center of the pins. Compatible Sleeve Part #: P3032.

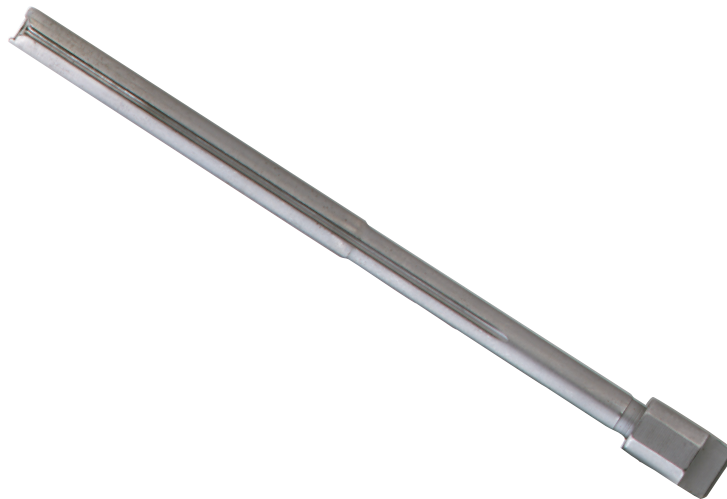

| Specifications | |
|-----------------------------|--|
| Wrap Function | Wrap |
| Wrap Type | Modified |
| Wire Gauge | 30-32 AWG (0.25-0.20 mm) |
| Maximum Insulation Diameter | 0.027” (0.69 mm) |
| Minimum Terminal Diagonal | 0.034” (0.86 mm) |
| Maximum Terminal Diagonal | 0.038” (0.96 mm) |
| Terminal Hole Depth | 0.75” (19.05 mm) |
| Terminal Hole Dia. | 0.040” (1.02 mm) |
| Effective Radius | 0.066” (1.67 mm) |
| Wrap Post Size | 0.025” (0.63 mm) |
| Features | Recommend for .025” square terminals on .100” center to center of the pins |
| Sleeve Part No. | P3032 and P3032INS (Sold Separately) |
| Length | 3” (76.2mm) |
| Weight | 0.048 lbs |
| UPC No | 811490013124 |