


**KEMET Part Number: C410C101K1G5TA**  
(C410C101K1G5TABULK)

Ceramic, AxiMax, 100 pF, 10%, 100 V, C0G, AxiMax, Commercial Standard

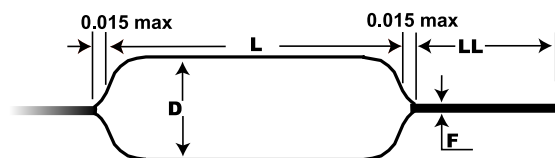

**Dimensions**

D	2.31mm MAX
L	4.32mm MAX
LL	25.4mm +0.025/-0.076mm
F	0.51mm +0.025/-0.076mm

**Packaging Specifications**

Packaging:	Bulk, Bag
Packaging Quantity:	300

**General Information**

Series:	AxiMax
Description:	AxiMax, Commercial Standard
RoHS:	Yes
Termination:	Tin
Failure Rate:	N/A

**Specifications**

Capacitance:	100 pF
Capacitance Tolerance:	10%
Voltage DC:	100 VDC
Dielectric Withstanding Voltage:	250 V
Temperature Range:	-55/+125C
Temperature Coefficient:	C0G
Dissipation Factor:	0.1%
Aging Rate:	0% Loss/Decade Hour
Insulation Resistance:	100 GOhms