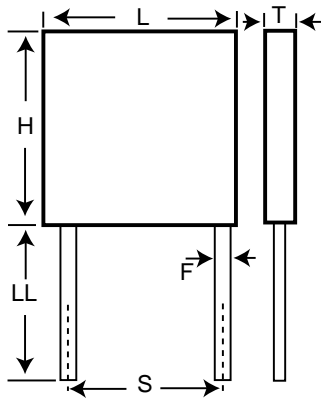


Ceramic, MoldedStandard, 0.1 uF, 10%, 50 V, X7R, Lead Spacing = 5.08mm

**Dimensions**

L	4.83mm +/-0.25mm
H	4.83mm +/-0.25mm
T	2.29mm +/-0.25mm
S	5.08mm +/-0.38mm
LL	31.75mm MIN
F	0.635mm +0.102/-0.051mm

**Packaging Specifications**

Packaging:	Bulk, Bag
Packaging Quantity:	100

**General Information**

Style:	Radial
Series:	MoldedStandard
Features:	Commercial
RoHS:	Yes
Termination:	Tin
Approvals:	EIA, UL

**Specifications**

Capacitance:	0.1 uF
Capacitance Tolerance:	10%
Voltage DC:	50 VDC
Dielectric Withstanding Voltage:	125 V
Temperature Range:	-55/+125C
Temperature Coefficient:	X7R
Dissipation Factor:	2.5%
Insulation Resistance:	10 MOhms