

Sealing cap - PROT-M12 FS - 1560251

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



M12 sealing cap for unoccupied M12 plugs of the sensor/actuator cable, flush-type plugs and I/O devices in the field

Why buy this product

- Sealing caps with external or inner thread
- Printed or unprinted marking labels

Key Commercial Data

Packing unit	5 STK
Minimum order quantity	5 STK
GTIN	 4 046356 183659
GTIN	4046356183659
Weight per Piece (excluding packing)	1.460 g
Custom tariff number	39235090
Country of origin	Germany

Technical data

Ambient conditions

Degree of protection	IP67
----------------------	------

Material

Flammability rating according to UL 94	HB
Material of grip body	PA 6
Sealing material	NBR

Characteristics head 2

Color	black
-------	-------

Standards and Regulations

Flammability rating according to UL 94	HB
--	----

Sealing cap - PROT-M12 FS - 1560251


Technical data

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

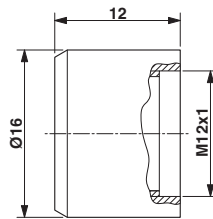

Classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27149110
eCl@ss 5.1	27149110
eCl@ss 6.0	27061801
eCl@ss 7.0	27061801
eCl@ss 8.0	27440208
eCl@ss 9.0	27440208

ETIM

ETIM 3.0	EC002040
ETIM 4.0	EC002040
ETIM 5.0	EC002314
ETIM 6.0	EC002314

UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	39121421

Approvals

Approvals

Sealing cap - PROT-M12 FS - 1560251


Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		EAC-Zulassung
-----	---	---------------
