



## Main

Range of product	Zelio Relay
Product or component type	Socket
Contact terminal arrangement	Separate
Product compatibility	Plug-in relay RSB (1 C/O)
Shape of pin	Flat
Device short name	RSZ
Sale per indivisible quantity	10

## Complementary

[I <sub>th</sub> ] conventional free air thermal current	12 A
[U <sub>e</sub> ] rated operational voltage	< 250 V AC
Tightening torque	<= 0.8 N.m (M3 screw(s))
Fixing mode	By screw mounting on panel Clip-on mounting on 35 mm symmetrical DIN rail
Marking	CE
Width	15.5 mm

## Environment


Connections - terminals	Screw connectors, flexible cable with cable end 1 x 0.25...1 x 2.5 mm <sup>2</sup> / AWG 22...AWG 14 Screw connectors, flexible cable with cable end 2 x 0.25...2 x 1 mm <sup>2</sup> / AWG 22...AWG 17 Screw connectors, solid cable without cable end 1 x 0.5...1 x 2.5 mm <sup>2</sup> / AWG 20...AWG 14 Screw connectors, solid cable without cable end 2 x 0.5...2 x 1.5 mm <sup>2</sup> / AWG 20...AWG 16
Standards	IEC 61984
Product certifications	CSA UL
Ambient air temperature for storage	-40...85 °C
Ambient air temperature for operation	-25...85 °C
IP degree of protection	IP20 conforming to EN/IEC 60529

Dielectric strength	2500 V
---------------------	--------

### Contractual warranty

Warranty period	18 months
-----------------	-----------

## Dimensions

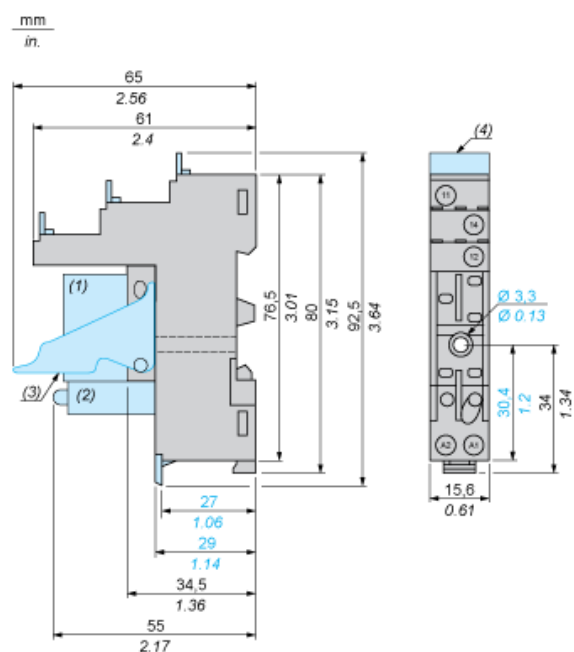

- (1) Relays
- (2) Protection module
- (3) Maintaining clamp
- (4) Legend

---

Wiring Diagram

---