


ZCKE05

limit switch head ZCKE - without lever left and right actuation

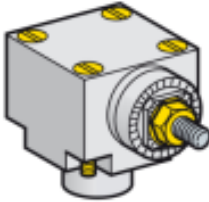

Main

Range of product	OsiSense XC
Series name	Standard format
Product or component type	Limit switch head
Device short name	ZCKE
Head type	Rotary head
Product compatibility	XCKJ
Associated lever	ZCKY91 ZCKY14 ZCKY51 ZCKY13 ZCKY81 ZCKY41 ZCKY11 ZCKY52 ZCKY59 ZCKY53 ZCKY43
Associated body	ZCKJ6 ZCKJ11 ZCKJ7 ZCKJ4 ZCKJ404H29 ZCKJ41 ZCKJ4104H29 ZCKJ7H7 ZCKJ4H7 ZCKJD35 ZCKJD31H29 ZCKJD39H7 ZCKJ21H29 ZCKJ11H7 ZCKJ6H7 ZCKJ9 ZCKJ5H29 ZCKJ8 ZCKJD31 ZCKJ8H7

ZCKJ7H29
 ZCKJ1H29
 ZCKJ6H29
 ZCKJ404H7
 ZCKJD31H7
 ZCKJ2
 ZCKJ404
 ZCKJ4H29
 ZCKJ9H7
 ZCKJ9H29
 ZCKJ5H7
 ZCKJD39H29
 ZCKJD37H7
 ZCKJ5
 ZCKJ21
 ZCKJ4104H7
 ZCKJ2H29
 ZCKJ21H7
 ZCKJ41H29
 ZCKJD35H7
 ZCKJ2H7
 ZCKJD35H29
 ZCKJ4104
 ZCKJ41H7
 ZCKJD37
 ZCKJ8H29
 ZCKJ1
 ZCKJ11H29
 ZCKJ1H7
 ZCKJD37H29
 ZCKJD39

Movement of operating head	Rotary
Type of operator	Without operating lever spring return
Type of approach	Lateral approach 1 or 2 programmable direction

Complementary

Switch actuation	CW and/or CCW From left and/or right
Positive opening	With
Head material	Metal

Environment

Ambient air temperature for operation	-25...70 °C
Ambient air temperature for storage	-40...70 °C
Environmental characteristic	Standard environment

Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0851 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold
Product end of life instructions	Need no specific recycling operations

Contractual warranty

Warranty period	18 months
-----------------	-----------