
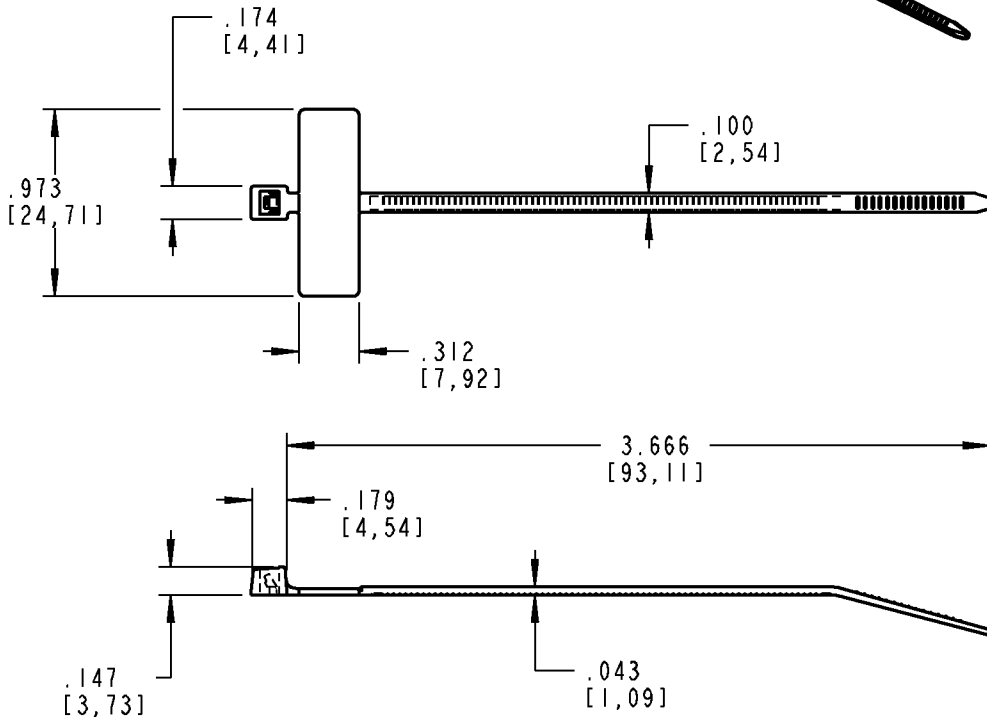


Catamount®

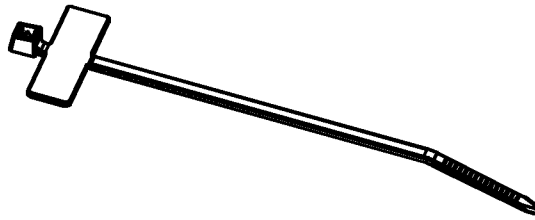


NOTES:

1. MATERIAL: NYLON 6,6 - COLOR: NATURAL
2. FLAMMABILITY: UL94V-2
3. OPERATING TEMPERATURE RANGE: -40°F [-40°C] TO 185°F [85°C]
4. MINIMUM TENSILE RATING: 18 LBS [80 N]
5. MAXIMUM WIRE BUNDLE: .750 [19,05]
6. INSTALLATION TOOL/SETTING: ERG50/1-3

CATALOG NUMBER

L - 4 - 18ID - 9 - *

* = PACKAGE QUANTITY- C = 100
M = 1,000

GENERAL NOTES		 www.tnb.com			
1. ALL DIMENSIONS ARE FOR REFERENCE ONLY. 2. DIMENSIONS IN BRACKETS [] ARE IN METRIC UNITS.					
REVISIONS		DESCRIPTION: MINIATURE IDENTIFICATION CABLE TIE			
- SEE ERN (****) FOR APPROVAL SIGNATURES & RELEASE DATE. PROJECT NO: ****		ORIGINAL PROJECT NO / (ERN NO)	SHEET NO:	REV. NO:	DRAWING NO:
		FM40182 / (2007414)	1 OF 1	-	WSD-000307