




Ty-Rap

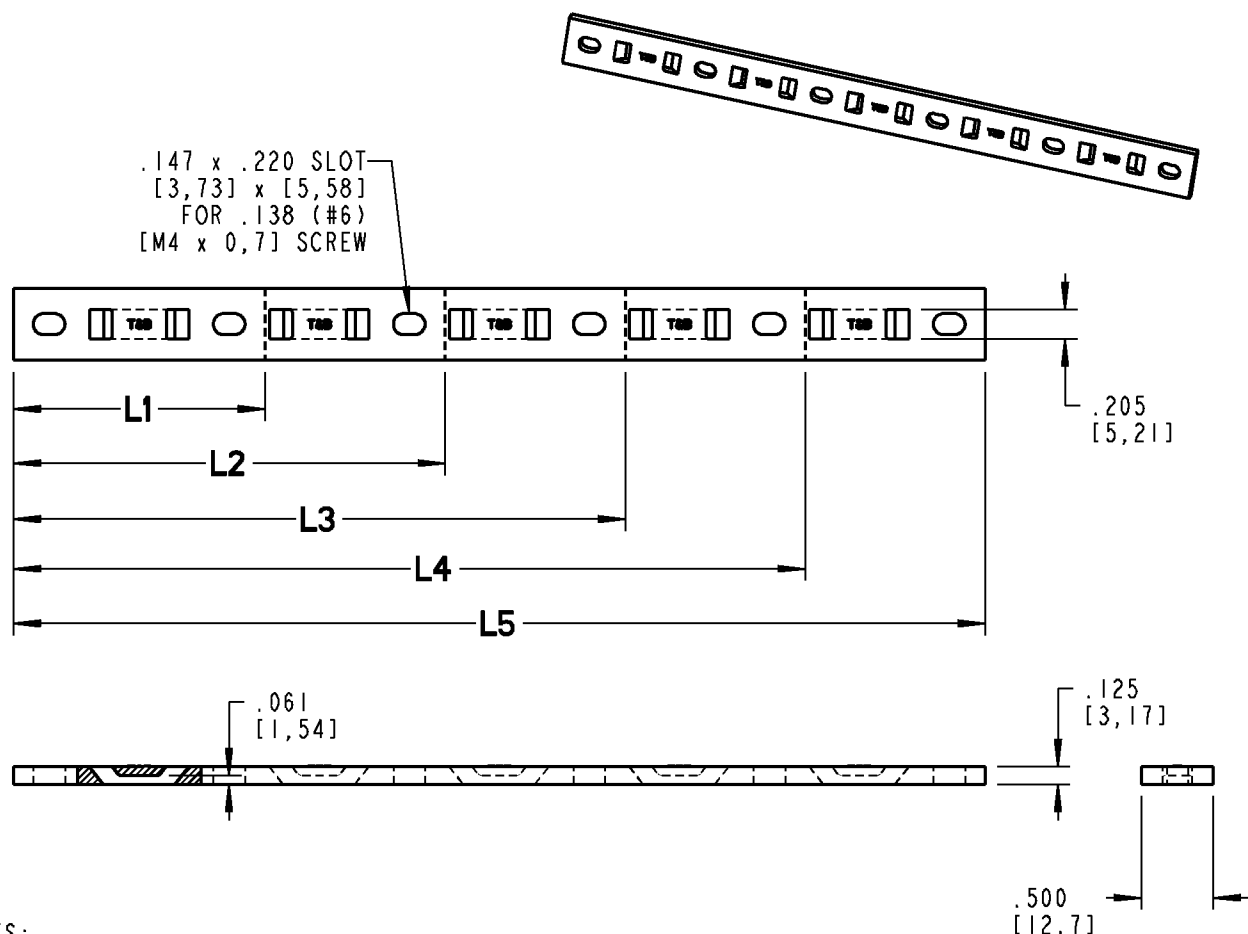

NOTES:

1. MATERIAL: NYLON 6,6- COLOR: NATURAL
2. FLAMMABILITY: UL94V-2
3. OPERATING TEMPERATURE RANGE: -40°F [-40°C] TO 185°F [85°C]
4. STANDARD PACKAGE QUANTITY: 100

CATALOG NUMBER	MAXIMUM TIE WIDTH	CAPACITY (BUNDLES)	(L) LENGTH	MIL STANDARD PART NO.
TC1101	.190 [4,82]	1	(L1) 1.750 [44,45]	MS3339-1
TC1102		2	(L2) 3.000 [76,2]	MS3339-2
TC1103		3	(L3) 4.250 [107,95]	MS3339-3
TC1104		4	(L4) 5.500 [139,7]	MS3339-4
TC1105		5	(L5) 6.750 [164,27]	MS3339-5

GENERAL NOTES

1. ALL DIMENSIONS ARE FOR REFERENCE ONLY.
2. DIMENSIONS IN BRACKETS [] ARE IN METRIC UNITS.

REVISIONS

SEE ERN (****)
FOR APPROVAL SIGNATURES
& RELEASE DATE.
PROJECT NO: ****

Thomas & Betts
www.tnb.com

DESCRIPTION:

MULTIPLE BUNDLE MOUNTING STRIP

ORIGINAL PROJECT NO / (ERN NO)

FM401183 / (2007645)

SHEET NO:

1 OF 1

REV. NO:

-

DRAWING NO:

WSD-000328