


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300550016](#)
Status: **Active**
Overview: [Brad® Industrial Ethernet Solutions](#)
Description: Brad® RJ-Lnxx® PC Board to Cable Ethernet Receptacle, 1" - 14 UNC Threads

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Industrial Receptacles
Series	130055
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad® Industrial Ethernet Solutions
Product Name	Brad®, RJ-Lnxx®
Type	PCB Mount
UPC	78678844310
Physical	
Coupling Type	External Thread
Gender	Female
Keyway	None
Length	0.60m
Material - Component	ABS
Mounting Thread Size	1" - 14 UNC
Net Weight	22.200/g
Orientation	Straight
Panel Mount	Front
Poles	N/A
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	N/A
Wire/Cable Type	N/A
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	125V DC
Material Info	
Engineering Number	ENSR1FB5
Reference - Drawing Numbers	
Sales Drawing	SD-130055-016

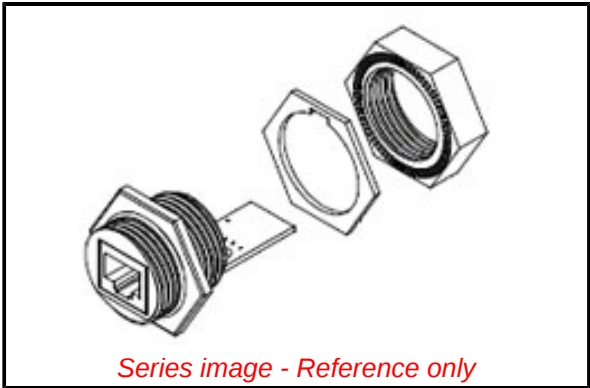

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - ED/30/2017 (7 July 2017) Halogen-Free Status Not Reviewed Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[130055 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION