

PROFESSIONAL TACTICAL PT™ 1L / PT™ 2L HIGH PERFORMANCE LITHIUM FLASHLIGHT

MARKET
APPLICATIONS: Law Enforcement, Security, Emergency Medical Services, Sporting Goods, Hardware/Tool, Consumer

DESCRIPTION:

Compact & powerful, the Professional Tactical series flashlights offer high and low intensity modes, strobe mode and the latest in power LED technology. The combination of small size and output from the C4® LED result in one of the brightest tactical personal carry lights for its' size. (Models also available with AA alkaline cells.)

CASE MATERIAL:

6000 series machined aircraft aluminum with anodized finish. Available in Black.

DIMENSIONS:

PT™ 1L: Length: 3.35 in. (8.51 cm) Head Diameter: 0.90 in. (2.29 cm) Barrel Diameter: 0.77 in. (1.96 cm)	PT™ 2L: Length: 4.68 in (11.89 cm) Major Diameter: 0.90 in. (2.29 cm) Barrel Diameter: 0.77 in. (1.96 cm)
--	---

WEIGHT:

PT™ 1L: 2.0 oz (57 grams) with battery	PT™ 2L: 2.8 oz (79 grams) with battery
--	--

LENS:

Tempered glass lens, o-ring sealed.

LIGHT SOURCE:

C4® LED technology, impervious to shock with a 50,000 hour lifetime.

LIGHT OUTPUT:

See charts for specific model. Optimized electronics provides regulated intensity.

ON/OFF:

Multi-function, push-button tactical tailswitch. One handed operation of momentary, variable intensity or strobe mode.

RUN TIME:

See charts for specific model. All claims to 10% of initial lumen output.

BATTERY:

PT™ 1L: One (1) 3 Volt CR123A Lithium battery. CR123A batteries have a shelf life of 10 years.	PT™ 2L: Two (2) 3 Volt CR123A Lithium batteries.
--	--

FEATURES:

 C4® LED technology for extreme brightness.
 LED Solid State Power Regulation provides maximum light output throughout battery life.
 IPX7 rated design; waterproof to 1 meter for 30 minutes.
 Anti-roll facecap.
 Removable pocket clip.
 Serialized for positive identification.

WARRANTY:


Streamlight warrants this product to be free of defect for a lifetime of use. We will repair, replace or refund the purchase price, at our option, of any Streamlight product that does not work or that you manage to break for as long as you own it. Of course, this limited lifetime warranty excludes abuse and batteries.

APPROVALS*:

 Meets applicable European Community directives. 
OPTIONAL
ACCESSORIES: Holster.

	PT™ 1L			PT™ 2L		
	FL1 STANDARD	HIGH	LOW	FL1 STANDARD	HIGH	LOW
OUTPUT		110 LUMENS	12 LUMENS		180 LUMENS	10 LUMENS
RUNTIME		1h 45min	14h		2h 30min	50h
DISTANCE		95m	30m		126m	35m
INTENSITY		2250 cd	225cd		4000 cd	300cd

1L Strobe Runtime: 3 hours 2L Strobe Runtime: 6 hours

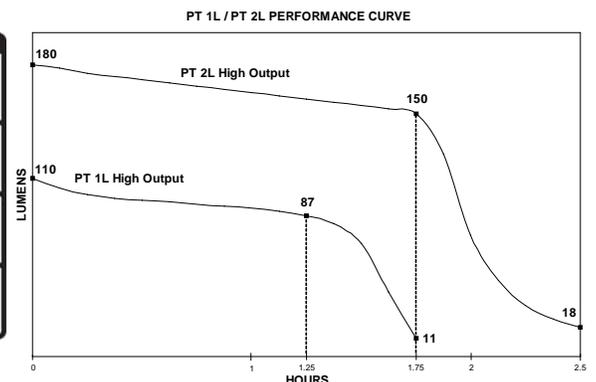

* See product for specific ratings.

All performance claims tested to ANSI/NEMA FL1-2009 Standard

Issued: 12/23/09

Revised: 03/15/10 Rev: 3

Made In China

Document #210