



Cable/DSL 4-Port Broadband Router TW100-S4W1CA(G1.0R)

TW100-S4W1CA 4-port Cable/DSL Broadband router provides the easiest and securest way to share your high-speed Cable/xDSL Internet connection. It has four 10/100Mbps half/full duplex switch ports that directly connect to workstations or uplink to another hub or switch. The TW100-S4W1CA also functions as a firewall for your PC, protecting your computer from hackers. It allows up to 253 users to access the Internet using a single ISP account. By sharing just one TW100-S4W1CA, one IP address, and one Cable/xDSL modem, dozens of network users can surf the Internet simultaneously. TRENDnet's Cable/DSL Modem Internet Station is a feature-rich product that provides cost-effective functionality and an easy configuration.

FEATURES

- Supports Cable/DSL Modem with Dynamic IP, Fixed IP, PPPoE or PPTP Connection Types
- Provides NAT (Network Address Port Translation) Firewall
- Supports Virtual Servers (Port Forwarding) and DMZ
- Supports Client Filtering by Date/Time (10 Entries) and Special Applications Filter (10 Entries)
- Supports MAC Address Control to Allow or Deny Access (32 Entries)
- Supports DNS (Domain Name System) Account for Server Mapping and Dynamic DNS Service
- Supports IPSec and PPTP VPN Pass-Through (when each VPN client connects to a different VPN endpoint)
- Supports UPnP (Universal Plug & Play)
- DHCP Server Supports up to 253 Users
- Easy Web Browser Configuration and Remote Management
- Flash Memory for Firmware Upgrade and Save/Restore Router Configurations
- 5 Year Warranty

Cable/DSL 4-Port Broadband Router


TW100-S4W1CA (G1.0R)

SPECIFICATIONS

Hardware	
Standards	• IEEE 802.3 10Base-T Ethernet; IEEE 802.3u 100Base-TX Fast Ethernet
Protocols	• TCP/IP, NAT, PPPoE, UPnP, HTTP, DHCP Server/Client, SNTP
WAN	• 1 x 10/100Mbps Port (Internet)
LAN	• 4 x 10/100Mbps Auto-MDIX Ports
Cabling	• Ethernet: Cat. 3, 4, 5, UTP EIA/ITA-568 100 Ohms, 100meters max. • Fast Ethernet: Cat. 5, UTP EIA/TIA-568 100 Ohms, 100meters max.
Data Transfer Rate	• Ethernet : 10Mbps/20Mbps (Half-Duplex/Full-Duplex) • Fast Ethernet: 100Mbps/200Mbps (Half-Duplex/Full-Duplex)
LED Indicator	• Power, WAN, Link/Act, LAN ports
Dimensions	• 154 x 110 x 33mm (6 x 4.3 x 1.3 inches)
Weight	• 225g (8 oz.)
Temperature	• 0° ~ 55°C (32°~ 131°F)
Humidity	• 95%(Non-Condensing)
Power Adapter	• 5V DC, 800mA
Certifications	• FCC & CE
Router	
Connection Type	• Dynamic IP, Static (Fixed) IP, PPPoE, PPTP
Firewall	• NAT, IP / MAC Address Filter, Domain / URL Blocking, Scheduling, UPnP
VPN	• IPSec, PPTP pass-through
Management	• Web Browser Configuration & Remote Management

NETWORKING SOLUTIONS

4-Port Cable/DSL Broadband Router (TW100-S4W1CA)

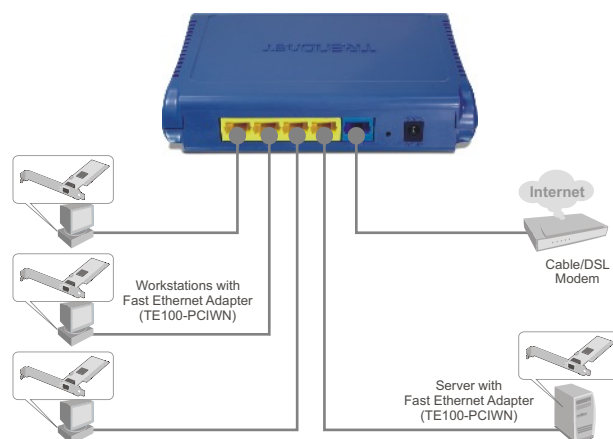

PACKAGE CONTENTS

- TW100-S4W1CA
- Multi-Language Quick Installation Guide
- User's Guide CD-ROM
- RJ-45 Cable (1.5m/5 ft)
- Power Adapter

RELATED PRODUCTS

TE100-PCIWN	10/100Mbps PCI Fast Ethernet Adapter
TE100-PCBUSR	10/100Mbps CardBus Ethernet Card
TE100-P1P	Print Server

ORDERING INFORMATION

TRENDnet®

20675 Manhattan Place, Torrance, CA 90501 USA
 Tel: 1-310-961-5500
 Fax: 1-310-961-5511
 Web: www.trendnet.com
 Email: sales@trendnet.com

To Order Please Call:

1-888-326-6061

