

4-Port USB 2.0 Automatic Printer Switch

GUB431



- Automatically* switch from one computer to another when connecting to a USB printer or multi-function printer
- Simply press a button to switch a USB device between computers - No software installation required
- Active-port LED lights indicate which computer has access to the USB device
- Switch-lock function prevents other users from switching the USB device and ensures data access consistency
- USB 2.0 support with data transfer rate up to 480Mbps and USB 1.1 backward compatible
- No external power supply needed

IOGEAR's USB 2.0 Automatic Printer Switch allows four PCs and / or Macs to share one printer or multi-function printer. Simply submit a print job and the printer automatically* switches to the preferred computer. The switch also enables four computers to easily share one external hard drive, scanner, or any USB device. No more plugging and unplugging between computers.


* Automatic switch function is software based and only available with USB printer or the printer function of a multi-function printer. For connecting and using other types of USB devices, you can switch by using the push-button on the USB switch or with the included software.



4-Port USB 2.0 Automatic Printer Switch

How does it work?

- Connect your USB device (i.e. printer, external hard drive, or scanner) to the USB-A connector
- Connect your computers (PC or Mac) to the USB-B connector
- Simply push the button to swap or enable automatic* switch between four computers

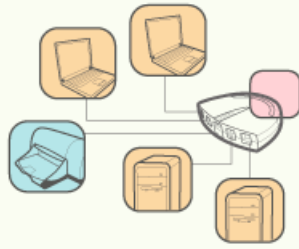

Requirements:

- Windows XP, Windows Vista 32-/64-bit, Windows 7 32-/64-bit
- Mac OS X v10.3.5 or later
- Available USB port (USB 2.0 port for High-Speed mode)

Package Contents:

- 1 x USB 2.0 Auto Switch
- 1 x 6 ft. USB A-B Cable
- 1 x User Manual
- 1 x Application CD
- 1 x Registration / Warranty Card

SPECIFICATIONS

Function	
Computer Connections	
Direct	USB Type-A
Connectors	
Console	1
Device Side	4
Environment	
Humidity	0-80% RH
Operation Temperature	41 to 104 degree Fahrenheit
Storage Temperature	-4 to 140 degree Fahrenheit
LEDs	
Port Status	Green - Online / Orange - Locked
Host Status	Orange - Online
Operating System Support	Windows ZP and above; Mac: 10.4.5, 10.5 and above
Power Consumption	DC 5V, 2.5W
Power Supply	USB Bus powered

Dimensions	
POP Information	
10" Peg Hook	4
6" Peg Hook	3
Unit Dimensions	
Width	4
Height	3
Depth	1
Unit Package Dimensions	
Width	6
Height	7.25
Depth	2.25
Master Carton	
Width	8
Height	7
Depth	15
Master Carton Qty.	6
Weight	
Master Carton Wt.	5 lb.
Unit Pack Wt.	0.7 lb.
Unit Wt.	0.2 lb.