


Overview

- Single gang device, white color.
- Compatible with decora style devices.
- Includes cover plate.
- Mounts in standard electrical boxes or low voltage brackets.
- Bluetooth 3.0 compliant - 32' range
- 3.5mm stereo and screw terminal outputs
- Includes AC adapter

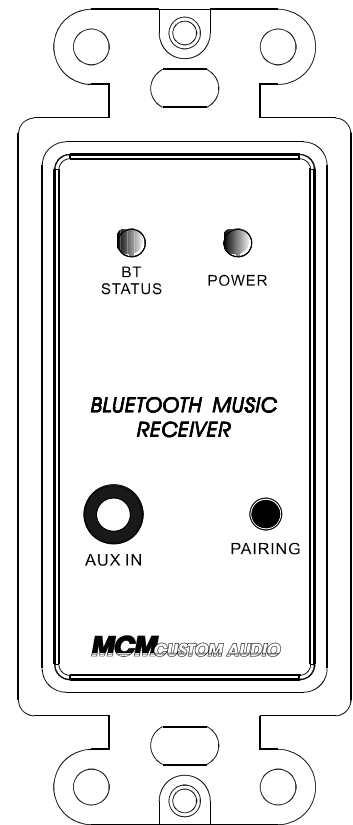

Specifications & Features



- Audio Inputs: Bluetooth receiver or stereo audio line level.
- AUX input is automatically selected when 3.5mm connector is inserted.
- Audio output: Stereo audio phone jack or 3-pin Screw terminal.
- Power input (5VDC): Power jack or 3-pin Screw terminal.
- Stereo audio output: For connection to standard amplifier inputs or powered speakers.
- Bluetooth version: 3.0 EDR compliant.
- Bluetooth receive Distance: 10 Meters.
- Power source: 5VDC/1A

Bluetooth Blue LED Status


- Pairing mode: 1s on/off flash 1 times
- Linked mode: Always on
- AUX mode: LED off

Bluetooth pairing


- § Press button 3 seconds to boot, press button 3 seconds to off.
- § The first pairing, hold down button 5 seconds to make the Bluetooth pairing boot.
- § The pairing timeout limit is 90 seconds.
- § If pairing timeout, you need hold down button 1 second to re-pairing.

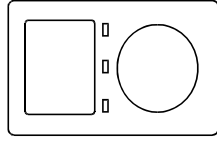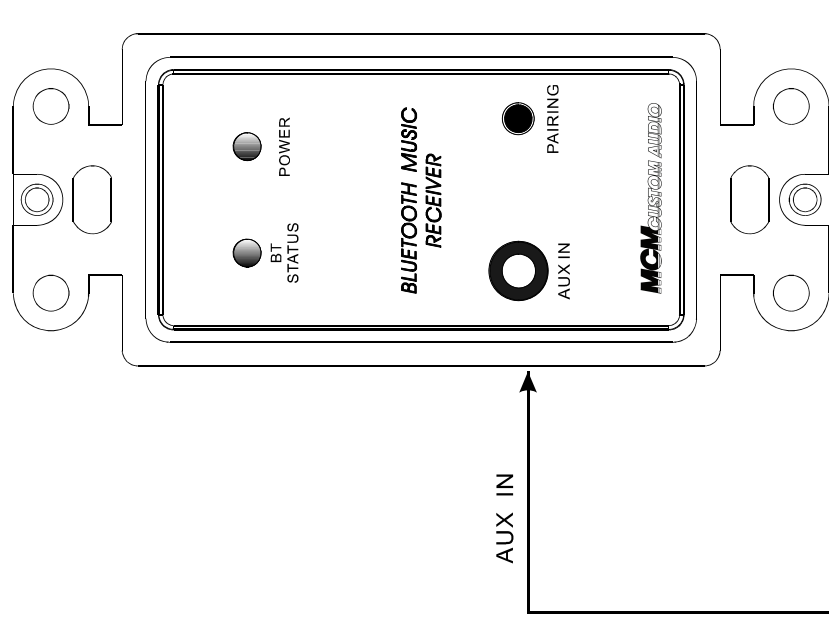

Audio Source

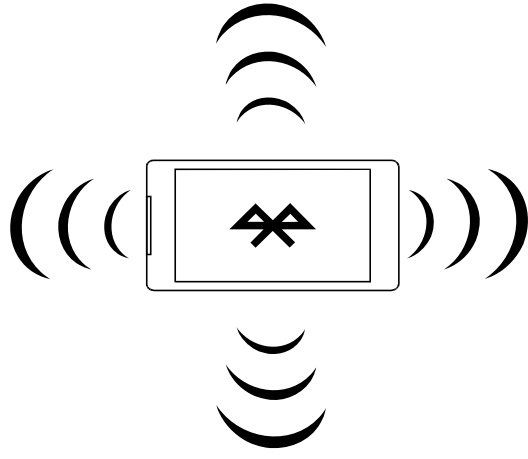

Back View

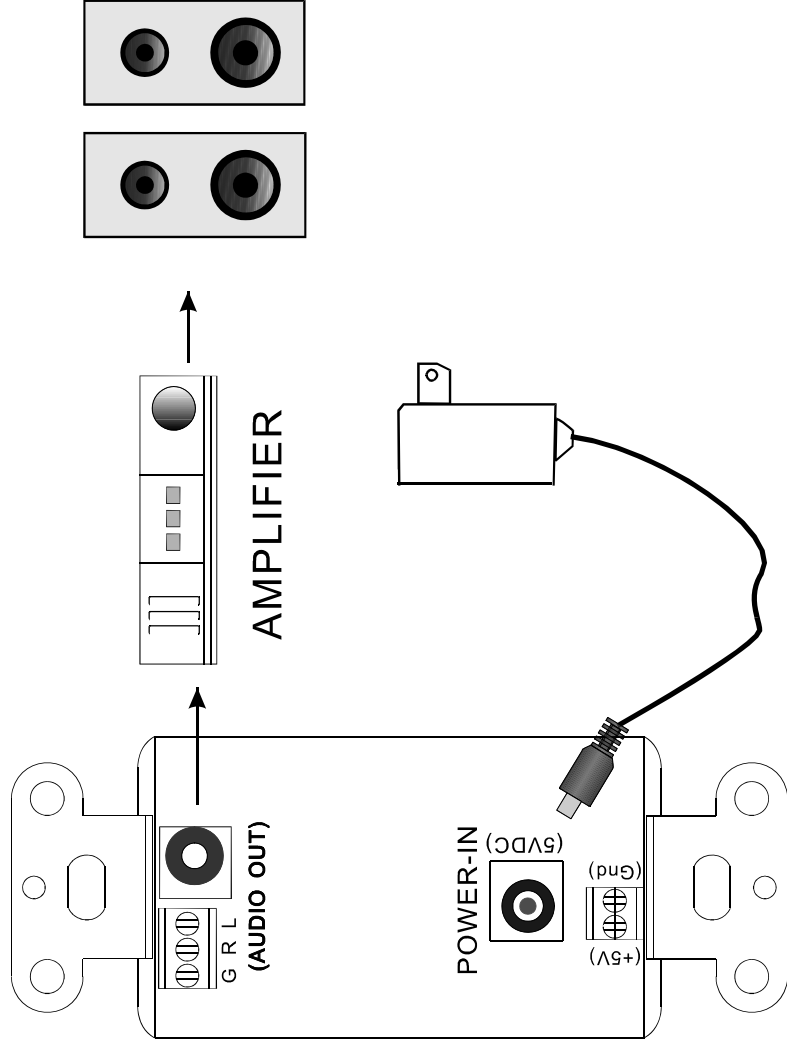

Setup Diagram