

Sunset Vintage Globe 80mm 2.5W (40W) 1800K 170lm E27 Non-Dimmable Lamp

Partcode: ILGLOBE27N001 / Page: 1



The wattage comparison is made between the Sunset LED Globe and its equivalent vintage incandescent decorative lamp. This offers a more accurate representation of the product's luminous efficacy. The ErP equivalent for reference is 2.5w (170lm) = 18W

Create a relaxing ambience with an ultra-warm (1800K), energy-saving LED filament lamp. The Sunset range has a retro look with tinted amber glass and an eye-catching vintage design.

Built using the latest LED filament technology to deliver an A+ energy rating and 93% energy savings compared to the incandescent lamp it replaces. Enjoy the classic aesthetic look but with an improved lifetime of 15,000 hours.

Product Details

Partcode: ILGLOBE27N001

Check Code: 821356

Range Name: Sunset

Placement / Application: Indoor, General Lighting

Product Type: Vintage Decorative

Warranty: 2 Years

CE / RoHS: Yes

Physical Data

Lamp Base: E27

Base Type: Edison screw

Globe Type: Globe 80

Globe Finish: Clear

Material: Glass

Construction: Glass shell, filament strip

Partcode: ILGLOBE27N001 / Page: 2

Physical Data

Length: 122mm
Width: 80mm
Weight (Unpackaged Single Unit): 47g
Lamp or Luminaire Shape: Round
Lamp Fixing: Pendant, Chandelier, Wall


Electrical Data

Voltage Range: 220-240V
Power Consumption: 2.5 Watts
Driver included: Yes
Electric Current: AC
Ampage: 41.00mA
Frequency Range: 50/60 Hz
Power Factor: ≥ 0.50
Wattage Equivalent: 40 Watts
Dimming: Non-dimmable
LVD Certified: Yes
EN: EN-62560

Light Data

Lumens: 170lm
Lumens per Watt: 68.0lm/W
Beam Angle: 300°
Correlated Colour Temperature (CCT): 1,800k
Colour Rendering Index (CRI): ≥ 80
LED Type: Filament
Instant on - Less than 1 second: Yes
Lifetime: 15,000 hrs
Switching Cycles: $>7,500$ X

Environmental

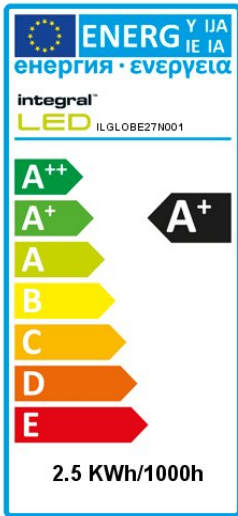

Energy Rating: A+

Lowest Operating Temperature: -20 degrees

Maximum Operating Temperature: 45 degrees

IP (Ingress Protection) Rating: IP20

Hg 0% (Mercury Free): Yes

Packaging



EAN Barcode (unit of 1): 5055788218296

Packaged Weight (Unit of 1): 96g

Length (unit of 1): 134mm

Width (unit of 1): 86mm

Depth (unit of 1): 86mm

Outer packaging info available on website

Product data last updated on: Monday, August 7, 2017 - 14:33