


## Sunset Vintage Globe 80mm 2.5W (40W) 1800K 170lm B22 Non-Dimmable Lamp

Partcode: ILGLOBB22N002 / Page: 1

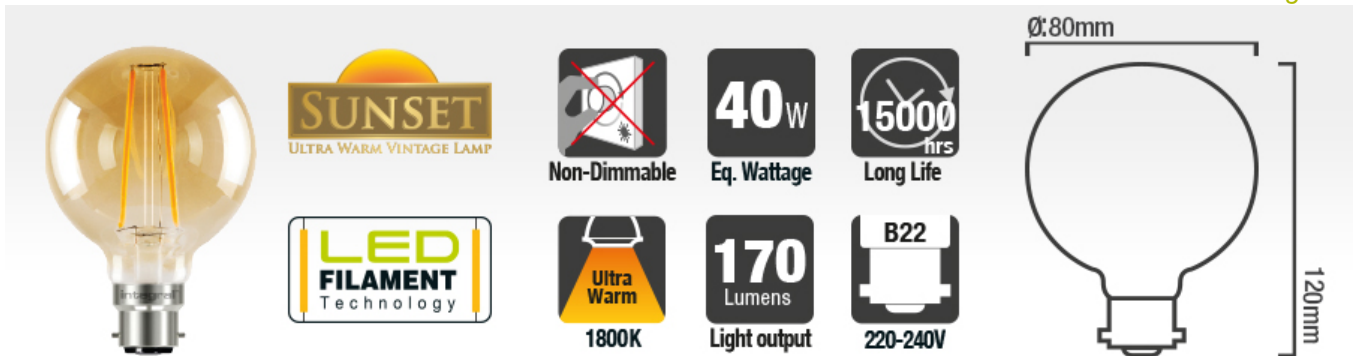

The wattage comparison is made between the Sunset LED Globe and its equivalent vintage incandescent decorative lamp. This offers a more accurate representation of the product's luminous efficacy. The ErP equivalent for reference is 2.5w (170lm) = 18W

Create a relaxing ambience with an ultra-warm (1800K), energy-saving LED filament lamp. The Sunset range has a retro look with tinted amber glass and an eye-catching vintage design.

Built using the latest LED filament technology to deliver an A+ energy rating and 93% energy savings compared to the incandescent lamp it replaces. Enjoy the classic aesthetic look but with an improved lifetime of 15,000 hours.

### Product Details

Partcode: ILGLOBB22N002

Check Code: 551882

Range Name: Sunset

Placement / Application: Indoor, General Lighting

Product Type: Vintage Decorative

Warranty: 2 Years

CE / RoHS: Yes

### Physical Data

Lamp Base: B22

Base Type: Bayonet cap

Globe Type: Globe 80

Globe Finish: Clear

Material: Glass

Construction: Glass shell, filament strip

**Physical Data**

Length: 120mm  
Width: 80mm  
Weight (Unpackaged Single Unit): 47g  
Lamp or Luminaire Shape: Round  
Lamp Fixing: Pendant, Chandelier, Wall


**Electrical Data**

Voltage Range: 220-240V  
Power Consumption: 2.5 Watts  
Driver included: Yes  
Electric Current: AC  
Ampage: 41.00mA  
Frequency Range: 50/60 Hz  
Power Factor:  $\geq 0.50$   
Wattage Equivalent: 40 Watts  
Dimming: Non-dimmable  
LVD Certified: Yes  
EN: EN-62560

**Light Data**

Lumens: 170lm  
Lumens per Watt: 68.0lm/W  
Beam Angle: 300°  
Correlated Colour Temperature (CCT): 1,800k  
Colour Rendering Index (CRI):  $\geq 80$   
LED Type: Filament  
Instant on - Less than 1 second: Yes  
Lifetime: 15,000 hrs  
Switching Cycles:  $>7,500$  X

## Environmental

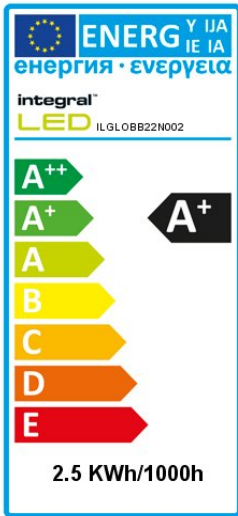

Energy Rating: A+

Lowest Operating Temperature: -20 degrees

Maximum Operating Temperature: 45 degrees

IP (Ingress Protection) Rating: IP20

Hg 0% (Mercury Free): Yes

## Packaging



EAN Barcode (unit of 1): 5055788218326

Packaged Weight (Unit of 1): 96g

Length (unit of 1): 134mm

Width (unit of 1): 86mm

Depth (unit of 1): 86mm

**Outer packaging info available on website**

*Product data last updated on: Monday, August 7, 2017 - 14:33*