


## Tripod work lamp with super-bright SMD LEDs

### Tripod SMD LED light SL DN 2806 S IP 54 1175600

#### Characteristics

- High-quality SMD LEDs from LG Innotek
- Casing made of aluminum pressure casting, surface coated.
- On/Off switch for light on the back.
- Floodlight can be pivoted and locked in place steplessly.
- Front pane made of safety glass.
- Very stable, robust tripod
- Stable steel pipe, powder coated
- Stepless height adjustment from 0.9m to 2m.
- Handy, reliable pipe clamping nuts.

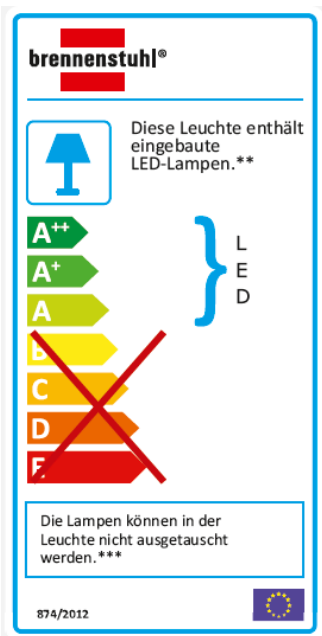

LED:  LG Innotek



Technical highlights

- Brand-name SMD LEDs from LG Innotek with a high degree of efficiency
- GS-certified product (light L DN 2806 S IP54)



Technical specifications

- Art. No.: 1175600
- Type description: SL DN 2806 S IP54 (light: L DN 2806 S IP54)
- LEDs: 28 x 0.6W SMD
- Power input: 20 W
- Flux: 1720 lm
- Efficiency: 86 lm/W
- Weighted energy consump.: 22 kWh/1000h
- Energy efficiency class: A
- Type of protection: IP 54
- Supply voltage: 220-240 V~ 50/60 Hz
- Color temperature: 5700 K
- LED service life: 50,000 hrs
- Radiation angle: approx. 110°
- Protection class: I
- Connection cable: 3m H05RN-F3G1,0
- Tripod height: 0.9m bis 2m
- Weight: approx. 3.9 kg