

09 02 240 T

Lineman's Pliers with tether attachment point

American style




- Improved version
- Now requires 50% less effort compared with conventional combination pliers due to an optimised transmission ratio
- Solid construction for heaviest strain; universally applicable
- Ergonomically optimised handle shape for firm contact to the hand and fatigue reducing operation
- Particularly effective cross-hatched knurled gripping zone in the jaws - for strong gripping and pulling
- Additional gripping zone below the joint for powerful leverage and pressing performance
- With cutting edges for soft and hard wire
- Cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- Vanadium electric steel, forged, multi stage oil-hardened
- Pliers with tether attachment point for mounting a fall protection

Article No.	09 02 240 T
EAN	4003773079941
Pliers	black atramentized
Head	polished
Handles	with multi-component grips, with integrated tether attachment point for a tool tether
Cutting capacities medium hard wire (diameter) Ø mm	4,6
Cutting capacities hard wire (diameter) Ø mm	3,0
Length mm	240
Net weight g	463



Gripping zone below the joint for powerful leverage

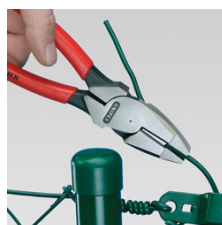

Cross-hatched, knurled gripping zone for firm gripping and pulling, e. g. for fence construction



Long cutting edges for cutting flat cables

technical change and errors excepted