

11 06 160 T


Insulation Stripper with tether attachment point



- For single, multiple and fine stranded conductors with plastic or rubber insulation up to 5.0 mm dia. or 10 mm² cable cross-section
- Easy adjustment to the required diameter of solid or stranded wire with knurled screw and lock nut
- Special tool steel, forged, oil-hardened
- Pliers with integrated, insulated tether attachment point for a tool tether



Article No.	11 06 160 T
EAN	4003773081418
Pliers	chrome plated
Handles	
Style	
Head	
Insulation standard	IEC 60900 DIN EN 60900
Nominal size	160 mm
Stripping capacities in square millimetres mm²	10,0
AWG	7
Stripping capacities (diameter) Ø mm	5,0
Length mm	160
Net weight g	168

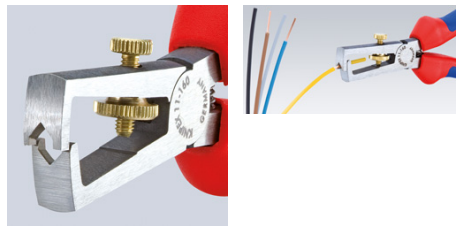

technical change and errors excepted