

25 06 160 T

Snipe Nose Side Cutting Pliers (Radio Pliers)


with tether attachment point



- Suitable for finer gripping and cutting work
- Pointed, half-round jaws
- Knurled gripping surfaces
- With cutting edges for soft, medium-hard and hard wire
- Cutting edges additionally induction hardened, cutting edge hardness approx. 61 HRC
- Vanadium electric steel, forged, multi stage oil-hardened
- Pliers with integrated, insulated tether attachment point for a tool tether



Article No.	25 06 160 T
EAN	4003773081432
Pliers	chrome plated
Handles	
Style	0
Head	
Insulation standard	IEC 60900 DIN EN 60900
Cutting capacities medium hard wire (diameter) Ø mm	2,5
Cutting capacities hard wire (diameter) Ø mm	1,6
T1 mm	9,0
W4 mm	3,0
T2 mm	2,5
L3 mm	50,0
W3 mm	16,5
Nominal size	160 mm
Length mm	160
Net weight g	156

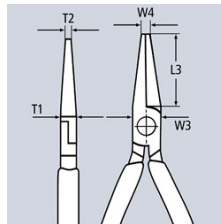

technical change and errors excepted