

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0466250200
Status: Active
Overview: Micro-Fit 3.0 Connector System Product Family
Description: Micro-Fit BMI™ Plug Housing, Single Row, Panel Mount, 2 Circuits, Nylon, UL 94V-0

Documents:

[Drawing \(PDF\)](#)
[Packaging Specification 466250000-PK-000 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)
[Product Literature \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series 46625
Application Power, Wire-to-Board, Wire-to-Wire
Overview Micro-Fit 3.0 Connector System Product Family
Product Literature Order No 987650-5984
Product Name Micro-Fit BMI™
UPC 887191386584

Physical

Circuits (maximum) 2
Color - Resin Black
Flammability 94V-0
Gender Plug
Glow-Wire Compliant No
Lock to Mating Part No
Material - Resin Nylon
Net Weight 1.323/g
Number of Rows 1
Packaging Type Bag
Panel Mount Yes
Pitch - Mating Interface 3.00mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40°C to +105°C


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Packaging Specification 466250000-PK-000
Sales Drawing SD-46625-001-001

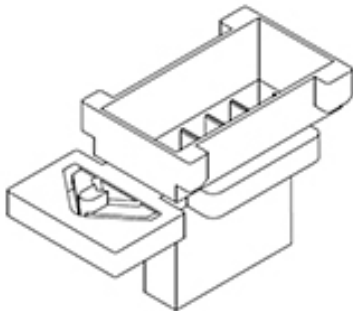

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

46625 Series

Mates With

46623 Micro-Fit BMI™ Receptacle Housing

Use With

43031 Micro-Fit 3.0™ Male Crimp Terminals

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION