


PS1240P02CT3

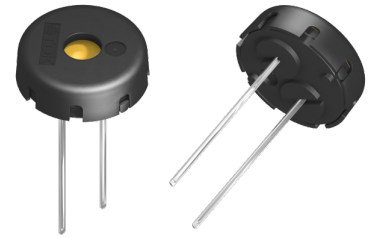

Applications	Commercial Grade
Series	PS
Status	Production
Terminal Shape	Pin Terminal



Size	
Outer Diameter(D)	12.20mm Nom.
Height(H)	3.50mm Nom.

Electrical Characteristics	
Sound Pressure Level (Min.)	60dB
Frequency	4kHz
Rated Input Voltage	3V(0-p)
Sound Pressure Level vs. Frequency	Please refer to the catalog

Other	
Operating Temperature Range	-10 to 70°C
Soldering Method	Wave (Flow)
Packing	Radial Taping Ammo Pack
Package Quantity	2500pcs
Weight per pc	0.42g

! Images are for reference only and show exemplary products.
! This PDF document was created based on the data listed on the TDK Corporation website.
! All specifications are subject to change without notice.